



品牌代码: 订购时, 填写品牌代码, 将可得到更快速的答复。

■焊式卡盘

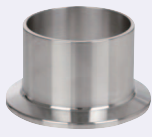


Type	材质
14AMPA、14MMPA、14WMPA	SUS304
14AMPAS、14MMPAS、14WMPAS	SUS316L

 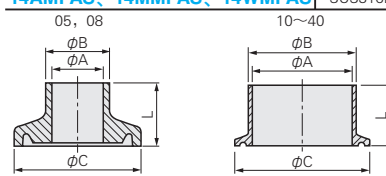


CAD 2D

■盲板




Type	材质
16AMPA	SUS304
16AMPAS	SUS316L




CAD 2D

■卡盘平形垫圈




Type	材质	Type	材质
13PGAE	EPDM	13PGAP	PTFE
13PGAS	SILICON	13PGAPE	PTFE+EPDM
13PGAV	VITON		

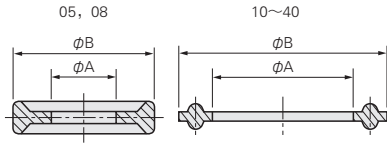


CAD 2D

■重型单铆钉卡箍

 


Type	材质
13MHHD	SUS304

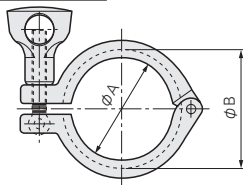


CAD 2D

■高压卡箍



Type	材质
13MHPD	SUS304

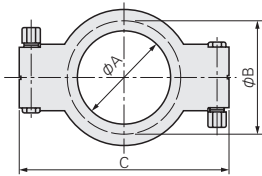

CAD 2D

型式	适用公称管径 (英寸)		A	B	C	14WMPA L	14MMPA L	14AMPA L
Type	公称尺寸							
14AMPA 14AMPAS 14MMPA 14MMPAS 14WMPA 14WMPAS	05	1/2	9.45	12.75	25.2	12.7	21.5	28.6
	08	3/4	15.75	19.05	25.2	12.7	21.5	28.6
	10	1.0	22.2	25.4	50.5	12.7	21.5	28.6
	15	1 1/2	34.9	38.1	50.5	12.7	21.5	28.6
	20	2.0	47.6	50.8	64	12.7	21.5	28.6
	25	2 1/2	60.3	63.5	77.5	12.7	21.5	28.6
	30	3.0	73	76.2	91	12.7	21.5	28.6
	40	4.0	97.6	101.6	119	15.8	21.5	28.6

型式	适用公称管径 (英寸)		A	L
Type	公称尺寸			
16AMPA 16AMPAS	05	1/2~3/4	25.2	5
	10	1.0~1 1/2	50.5	6.3
	20	2.0	64	6.3
	25	2 1/2	77.5	6.3
	30	3.0	91	6.3
40	4.0	119	7.9	

型式	适用公称管径 (英寸)		A	B
Type	公称尺寸			
13PGAE 13PGAS 13PGAV 13PGAP 13PGAPE	05	1/2	9.9	21.8
	08	3/4	16.3	21.8
	10	1.0	22.7	50
	15	1 1/2	35.9	50
	20	2.0	48.6	63.5
	25	2 1/2	61.3	76.2
	30	3.0	74	88.9
40	4.0	98.6	118	

型式	适用公称管径 (英寸)		φA	φB
Type	公称尺寸			
13MHHD	10	1~1 1/2	44.4	53.6
	20	2.0	57.8	67
	25	2 1/2	71.4	80.6
	30	3.0	84	94.2
	35	3 1/2	99	109.2
	40	4.0	110	122.2
60	6.0	155.4	170.4	

型式	适用公称管径 (英寸)		φA	φB	C
Type	公称尺寸				
13MHPD	05	1/2~3/4	20	28	55
	10	1.0~1 1/2	43.3	52	103
	20	2.0	56.4	65.5	114.5
	25	2 1/2	69.5	79	127
	30	3.0	77.5	92.5	140.6
40	4.0	108.8	120.5	165	



Type 14WMPA - 公称尺寸 05



3~天发货
*本产品发货时间不含周六。



便捷询价 4种方法 P.49

更多产品, 请使用您的帐户登录 MiSUMI-VONA e-Catalog <http://cn.misumi-ec.com>

照片			
名称	CVA 夹式蝶阀	WVRAS 焊式止回阀	14LWS 长形平接头